


KEMET Part Number: 080MS22ABMA1STD
(A902GJ080V220A)

KEMET

a YAGEO company

MS/A902, Aluminum Electrolytic, 80 uF, -0/+25%, 220 VAC, -20/+60°C

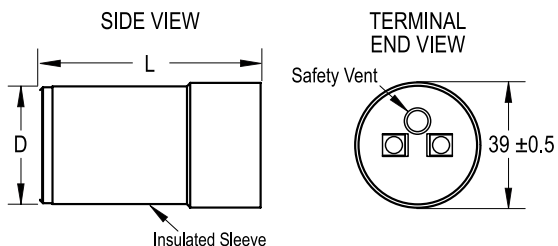

General Information	
Series:	MS/A902
Dielectric:	Aluminum Electrolytic
Description:	Motor Start Aluminum Electrolytic
RoHS:	Yes
Lead:	Quick Connect
AEC-Q200:	No
Halogen Free:	Yes
Shelf Life:	156 Weeks

Dimensions	
D	38mm +/-0.5mm
L	90mm MAX

Specifications	
Capacitance:	80 uF
Capacitance Tolerance:	-0/+25%
Voltage AC:	220 VAC
Temperature Range:	-20/+60°C
Rated Temperature:	60°C
Life:	500 Hrs

Packaging Specifications	
Packaging:	Bulk, Bag

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

KEMET

a YAGEO company