


KEMET Part Number: B-06-R-25
(UDLB00006R2500)

KEMET
a YAGEO company

KEMET, BEAD L, DC Line Filters, Normal Mode

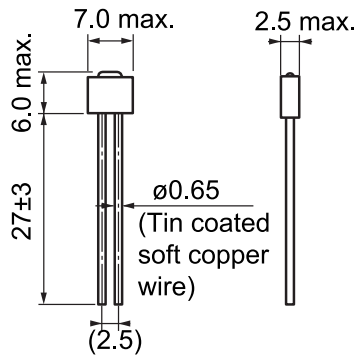

General Information

Series:	BEAD L
Style:	Through-Hole
RoHS:	Yes

Specifications

Temperature Range:	-20/+70°C
---------------------------	-----------

Dimensions

D	2.5mm MAX
L	6mm MAX
W	7mm MAX
LL	27mm +/-3mm
S	2.5mm NOM
Wire Size	0.65mm

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	100
Component Weight:	500 mg

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

KEMET
a YAGEO company