


C28, Film, Film/Foil Polypropylene, Motor Run, 10 uF, 5%, 470 VAC

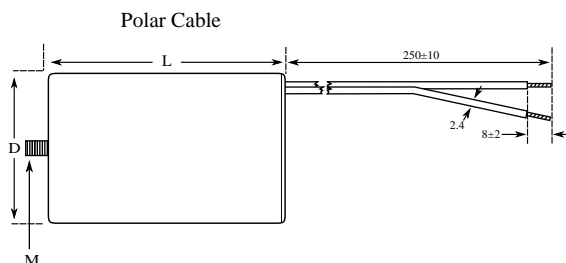

General Information	
Series:	C28
Dielectric:	Film/Foil Polypropylene
Style:	Can
Description:	Plastic Case and Cover, Ultra Sonically Welded Seal
Features:	Ultra Sonically Welded Seal, Safety Class S3, UL_94 V0 Disk
RoHS:	Yes
Termination:	Tin Copper
Lead:	Cables
Qualifications:	UL, VDE, UL (Construction Only), UL_94 V0 Disk

Dimensions	
D	35mm +/-1mm
L	69.5mm +/-2mm

Specifications	
Capacitance:	10 uF
Capacitance Tolerance:	5%
Voltage AC:	470 VAC
Temperature Range:	-25/+85°C
Rated Temperature:	85°C
Max dV/dt:	20 V/us

Packaging Specifications	
Mounting:	Bolt-M8x26
Packaging:	Bulk, Bag
Packaging Quantity:	86