


KEMET Part Number: EFF4(05)-240X80T0800
 (UFSEF4050JT080, EFF4(05)240X80T0800)

KEMET, EFF4, Flex Suppressors, Noise Suppression

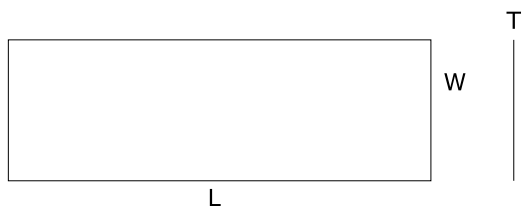

General Information	
Series:	EFF4
Style:	Sheet
Description:	Flex Suppressor Flame Retardant Type
Features:	Flame Retardant Type
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No.E176124, AEC-Q200
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions	
Sheet Size	240x80mm
L	240mm NOM
W	80mm NOM
T	0.5mm NOM

Specifications	
Temperature Range:	-40/+125°C
Magnetic Permeability:	140 u At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.7 Atm TYP

Packaging Specifications	
Weight:	36.3 g

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.