


KEMET, FLLD3-MH, EMI/RFI Filters, Noise Suppression, 520 VAC, 7 A, 160x40x70mm

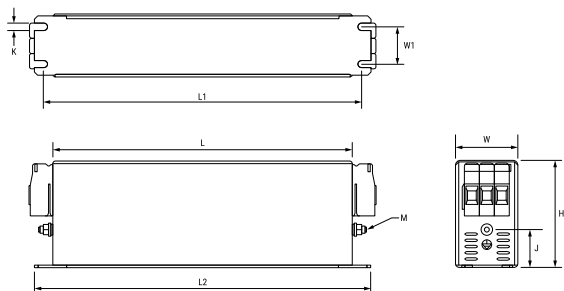

General Information	
Series:	FLLD3-MH
Style:	Chassis Mount
Description:	EMI Filter, Chassis Mount, Motor Drives
Features:	Three Phase, High Performance, High Voltage
RoHS:	Yes
Qualifications:	IEC/EN 60939, UL 1283
Lead:	Threaded Studs M5

Dimensions	
L	160mm NOM
W	40mm NOM
H	70mm NOM
L1	180mm NOM
L2	190mm NOM
W1	20mm NOM
J	22mm NOM
K	4.5mm NOM
M (Earth)	Threaded Studs M5
Lead	Threaded Studs M5

Specifications	
Voltage AC:	520 VAC, 300 VAC
Rated Frequency:	50-60 Hz
Ripple Current:	7 A (50°C)
Rated Temperature:	50°C
Temperature Range:	-25/+100°C
Climate Category:	25/100/21
Test Voltage DC (P to P):	2250 VDC
Test Voltage DC (P to E):	3000 VDC
Voltage:	2250 VDC (Test P to P), 3000 VDC (Test P to E)
Power Loss:	4 W (25°C 50 Hz)
Leakage Current:	3.1 mA

Packaging Specifications	
Packaging:	Bulk
Packaging Quantity:	1
Weight:	500 g