


KEMET, FLLD3-MH, EMI/RFI Filters, Noise Suppression, 520 VAC, 180 A, 350x120x170mm

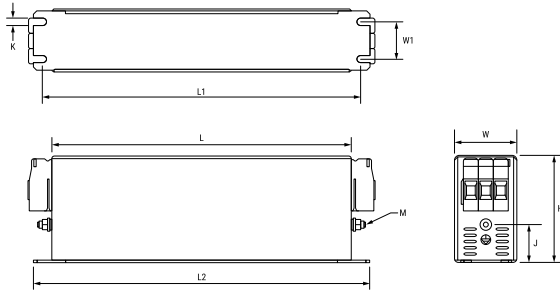

General Information	
Series:	FLLD3-MH
Style:	Chassis Mount
Description:	EMI Filter, Chassis Mount, Motor Drives
Features:	Three Phase, High Performance, High Voltage
RoHS:	Yes
Qualifications:	IEC/EN 60939, UL 1283
Lead:	Threaded Studs M10

Dimensions	
L	350mm NOM
W	120mm NOM
H	170mm NOM
L1	365mm NOM
L2	380mm NOM
W1	102mm NOM
J	47mm NOM
K	6.5mm NOM
M (Earth)	Threaded Studs M10
Lead	Threaded Studs M10

Specifications	
Voltage AC:	520 VAC, 300 VAC
Rated Frequency:	50-60 Hz
Ripple Current:	180 A (50°C)
Rated Temperature:	50°C
Temperature Range:	-25/+100°C
Climate Category:	25/100/21
Test Voltage DC (P to P):	2250 VDC
Test Voltage DC (P to E):	3000 VDC
Voltage:	2250 VDC (Test P to P), 3000 VDC (Test P to E)
Power Loss:	45 W (25°C 50 Hz)
Leakage Current:	4.7 mA

Packaging Specifications	
Packaging:	Bulk
Packaging Quantity:	1
Weight:	5.1 kg