


KEMET Part Number: JSNEJ5350KB6L0
(SNEJ5350KB6L0)

JSN, Film, Metallized Polyester Stacked, Automotive Grade, 35 uF, 10%, 63 VAC, 100 VDC, 105°C, 17.3X30X15.4, 15.4mm

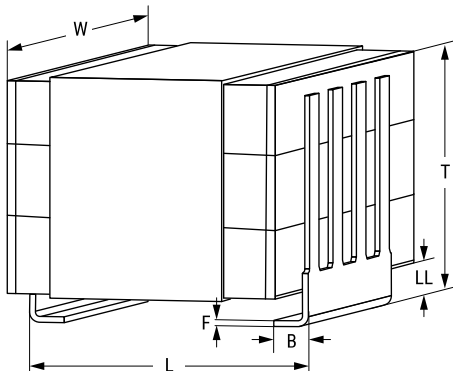

Dimensions

Chip Size	17.3X30X15.4
L	17.3mm MAX
W	30mm MAX
T	15.4mm MAX
LL	2mm +/-1mm
F	0.3mm +/-0.1mm
B	2mm +/-1mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	252

General Information

Series:	JSN
Dielectric:	Metallized Polyester Stacked
Style:	SMD Chip
RoHS:	Yes
Lead:	J Leads
Qualifications:	AEC-Q200
AEC-Q200:	Yes
Shelf Life:	104 Weeks

Specifications

Capacitance:	35 uF
Capacitance Tolerance:	10%
Voltage AC:	63 VAC
Voltage DC:	100 VDC
Temperature Range:	-55/+125°C
Rated Temperature:	105°C
Dissipation Factor:	1.00% 1kHz
Max dV/dt:	27 V/us