


KEMET, LF, EMI/RFI Filters, Noise Suppression, 250 VAC, 250 V, 30 A

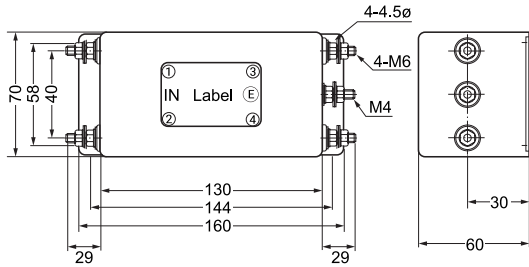

#### Dimensions

<b>L</b>	160mm NOM
<b>W</b>	70mm NOM
<b>H</b>	60mm NOM
<b>Lead</b>	Screw Terminals

#### Packaging Specifications

<b>Packaging:</b>	Tray, Box
<b>Packaging Quantity:</b>	12
<b>Weight:</b>	1.2 kg

#### General Information

<b>Series:</b>	LF
<b>Style:</b>	Metal Box
<b>Description:</b>	Metal Box
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	30 K Self-Temperature Rise Max.
<b>Lead:</b>	Screw Terminals
<b>Terminal Type:</b>	Screw

#### Specifications

<b>Voltage AC:</b>	250 VAC
<b>Voltage:</b>	250 VDC, 1500 VAC Withstanding Voltage 1 Min. Line to Ground
<b>Rated Current:</b>	30 A (AC/DC)
<b>Ripple Current:</b>	30 A (AC/DC)
<b>Rated Temperature:</b>	55°C
<b>Temperature Range:</b>	-20/+55°C
<b>Leakage Current:</b>	1 mA MAX (250 V 60 Hz)
<b>Resistance:</b>	300 MOhms MIN Insulation 500 VDC 1 Min. Line To Ground