


KEMET Part Number: M4(100)-90X70T0800
(UFSM40010KT080)

KEMET

a YAGEO company

KEMET, M4, Flex Suppressors, RFID

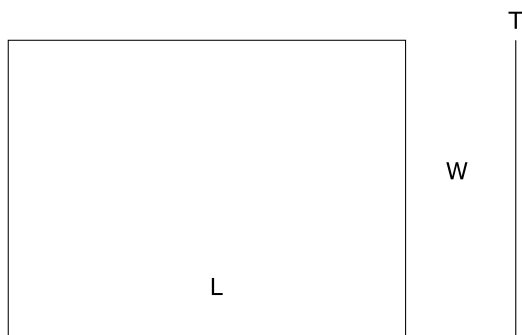

General Information	
Series:	M4
Style:	Sheet
Description:	Flex Suppressor Halogen Free Type
Features:	High Magnetic Permeability Type, Low Magnetic Loss Type
RoHS:	Yes
Qualifications:	UL94 HB, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions	
Sheet Size	90x70mm
L	90mm NOM
W	70mm NOM
T	0.1mm NOM

Specifications	
Temperature Range:	-40/+105°C
Magnetic Permeability:	40 μ At 13.56MHz
Effective Frequency:	13.56 MHz Max
Resistance:	10 MOhms MIN
Specific Gravity:	3.1 Atm TYP

Packaging Specifications	
Weight:	2.08 g

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

KEMET

a YAGEO company