


KEMET Part Number: MPXV1D1235LR15
(UPI2X11235VR15)

KEMET, MPXV, Power, 0.15 uH, 20%, 1235(5350)

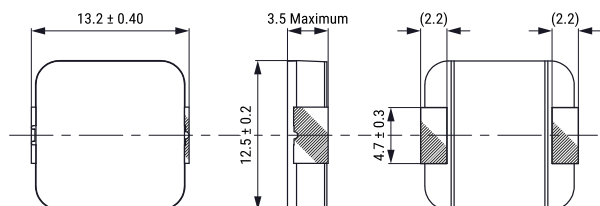

Dimensions

Dimensions	
L	13.2mm +/-0.4mm
W	12.5mm +/-0.2mm
T	3.5mm MAX
LL	2.2mm NOM
G	4.7mm +/-0.3mm

Packaging Specifications

Packaging:	T&R, 330mm
Packaging Quantity:	500

General Information

Series:	MPXV
Style:	SMD
Chip Size:	1235(5350)
Description:	Surface Mount Inductor
Features:	Power Inductors
RoHS:	Yes
Qualifications:	AEC-Q200
AEC-Q200:	Yes
Core:	Composite
Miscellaneous:	40 (K) Temperature Rise Max.

Specifications

Inductance:	0.15 uH
Inductance Tolerance:	20%
Temperature Range:	-55/+155°C
Shielded:	Yes
Current:	39.9 A (Irms, 40C Rise By Self Heating), 54 A (Isat, 20% Drop In Inductance), 85 A (Isat, 30% Drop In Inductance)
DC Resistance:	1.3 mOhms
Self-Resonant Frequency:	128 MHz