


KEMET Part Number: MR-2
(USEZ2000000000)

KEMET, MR, Current, Round - Toroidal, Zero Phase, High Sensitivity, Compact

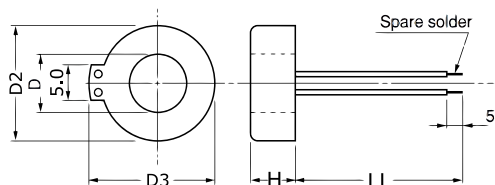

General Information	
Series:	MR
Type:	Current
Style:	Round - Toroidal
Description:	Zero-Phase Current Transformers
Features:	High Sensitivity, Compact
Lead:	Cables
RoHS:	Yes
Notes:	Measurement Conditions: f=60Hz, R=300 Ohms, I _o =22.5 mAmps

Dimensions	
D	8.9mm MIN
H	8.3mm MAX
D2	21.8mm MAX
D3	24.7mm MAX
D4	5mm NOM
LL	80mm +/-3mm

Specifications	
Temperature Range:	-20/+80°C
Voltage DC:	8 mV MIN (Output)
Current:	30 Amps
Resistance:	30 Ohms
Miscellaneous:	Overinput characteristics (After DC5A input) = 10% MAX.

Packaging Specifications	
Packaging:	Tray
Packaging Quantity:	480
Weight:	5.9 g