


**KEMET Part Number: NBL45282H-A3**  
(UPCNBL45252HA3)

KEMET, NBL, Transducers, Single-layer

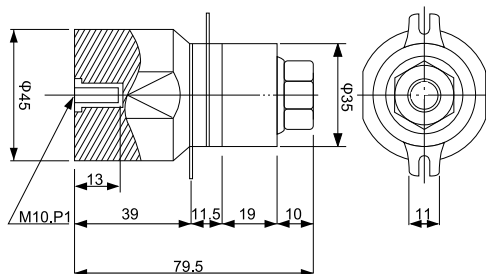

#### Dimensions

<b>D</b>	45mm NOM
<b>L</b>	79.5mm NOM

#### Packaging Specifications

<b>Weight:</b>	400
<b>Packaging:</b>	Bulk Tray, Box
<b>Packaging Quantity:</b>	30

#### General Information

<b>Style:</b>	Bolt-On
<b>Description:</b>	Langevin Bolt-On Transducers
<b>RoHS:</b>	With Exemptions
<b>REACH:</b>	SVHC (Pb – CAS 7439-92-1)
<b>Notes:</b>	Horn Construction; Output Surface Has Step Or Horn Shape.

#### Specifications

<b>Series:</b>	NBL
<b>Capacitance:</b>	4000 pF
<b>Resonant Frequency:</b>	28 kHz
<b>Dynamic Admittance:</b>	40msec
<b>Mechanical Q:</b>	500 Qm
<b>Allowable Velocity:</b>	40 cm/S
<b>Allowable Power:</b>	50
<b>Temperature Range:</b>	-40/+120°C