


KEMET Part Number: PMR210ME6100M100R30
(P410EE104M250AH101)

PMR210, Film, Metallized Paper, Resistor/Capacitor, 0.1 uF, 20%, 1000 VDC, 85°C, Lead Spacing = 25.4mm

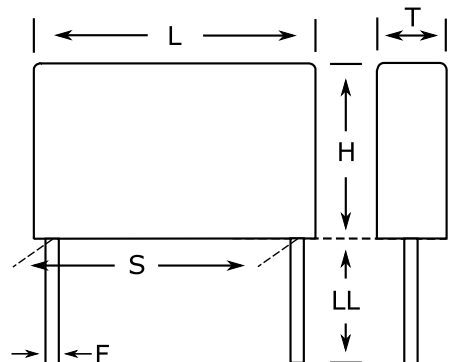

Dimensions

L	30.5mm MAX
H	16.1mm MAX
T	10.6mm MAX
S	25.4mm +/-0.4mm
LL	30mm +5mm
F	1mm +/-0.05mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	150

General Information

Series:	PMR210
Dielectric:	Metallized Paper
Style:	Radial
Features:	RC Unit approved
RoHS:	Yes
Lead:	Wire Leads
Qualifications:	ENEC, UL, cUL
AEC-Q200:	No
Construction:	Molded
Miscellaneous:	Resistor= 100 Ohms.
Notes:	Not For New Design, Please Use The New P410 Series @ 300 VAC.

Specifications

Capacitance:	0.1 uF
Capacitance Tolerance:	20%
Voltage AC:	250 VAC
Voltage DC:	1000 VDC
Temperature Range:	-40/+85°C
Rated Temperature:	85°C
Insulation Resistance:	3 GOhms
Safety Class:	X1