


KEMET, PLT, Pulse Transformers, PLT

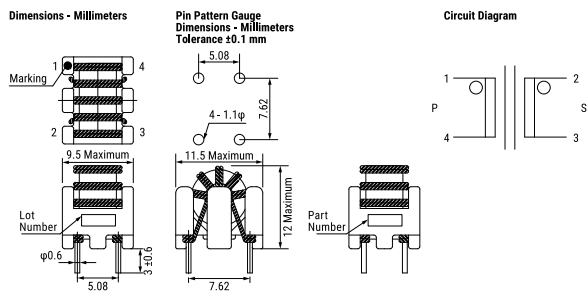

General Information	
Series:	PLT
Style:	Through-Hole
Features:	Proprietary Ferrite Material, Flat Insertion Loss Characteristics, UL94 V-0 Flame Retardant Rated Base
RoHS:	Yes
Qualifications:	UL94V-0
Miscellaneous:	Operating Temperature Range Includes Self-temperature Rise.

Dimensions	
L	9.5mm MAX
W	11.5mm MAX
H	12mm MAX
LL	3mm +/-0.6mm
S	5.08mm NOM

Specifications	
Voltage AC:	110 VAC Maximum, 3600 VAC (Dielectric, 2 Seconds Between Coil and Coil, No Abnormality)
Temperature Range:	-25/+100°C
DC Resistance:	55 mOhms

Packaging Specifications	
Packaging:	Bulk, Box
Packaging Quantity:	900
Weight:	1.3 g

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.