


**KEMET Part Number: PMR205AB6100M100R30**  
(P405QE104M125AH101)



PMR205/P405, Film, Metallized Paper, Resistor/Capacitor, 0.1 uF, 20%, 250 VDC, 85°C, Lead Spacing = 15.2mm

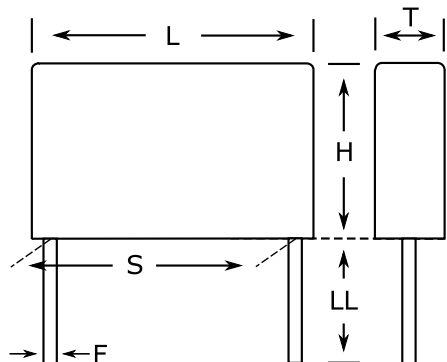

General Information	
Series:	PMR205/P405
Dielectric:	Metallized Paper
Style:	Radial
Features:	RC Unit not approved
RoHS:	Yes
Lead:	Wire Leads
AEC-Q200:	No
Construction:	Molded
Miscellaneous:	Resistor Tolerance: +/-30%. Resistor= 100 Ohms.

Dimensions	
L	18.5mm MAX
H	10.5mm MAX
T	5.2mm MAX
S	15.2mm +/-0.4mm
LL	30mm +5mm
F	0.8mm +/-0.05mm

Specifications	
Capacitance:	0.1 uF
Capacitance Tolerance:	20%
Voltage AC:	125 VAC
Voltage DC:	250 VDC
Temperature Range:	-40/+85°C
Rated Temperature:	85°C
Insulation Resistance:	3 GOhms
Safety Class:	X2

Packaging Specifications	
Packaging:	Bulk, Bag
Packaging Quantity:	500

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

