


KEMET, RG, EMI/RFI Filters, Noise Suppression, 250 VAC, 250 V, 8 A

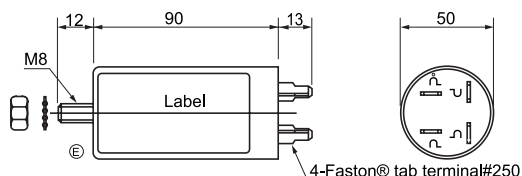

### General Information

<b>Series:</b>	RG
<b>Style:</b>	Metal Cylinder
<b>Description:</b>	Noise Filters
<b>RoHS:</b>	Yes
<b>Qualifications:</b>	TUV
<b>Miscellaneous:</b>	55 K Self-Temperature Rise Max.
<b>Lead:</b>	Fast On
<b>Terminal Type:</b>	Faston

### Dimensions

<b>D</b>	50mm NOM
<b>L</b>	90mm NOM
<b>LL</b>	13mm NOM
<b>L1</b>	12mm NOM
<b>Lead</b>	Fast On

### Packaging Specifications

<b>Packaging:</b>	Tray, Box
<b>Packaging Quantity:</b>	25
<b>Weight:</b>	320 g

### Specifications

<b>Voltage AC:</b>	250 VAC
<b>Voltage:</b>	250 VDC, 1500 VAC Withstanding Voltage 1 Min. Line to Ground
<b>Rated Current:</b>	8 A (AC/DC)
<b>Ripple Current:</b>	8 A (AC/DC)
<b>Temperature Range:</b>	-25/+55°C
<b>Leakage Current:</b>	1 mA MAX (250 V 60 Hz)
<b>Resistance:</b>	100 MOhms MIN Insulation 500 VDC 1 Min. Line To Ground