


KEMET, RG, EMI/RFI Filters, Noise Suppression, 250 VAC, 250 V, 8 A

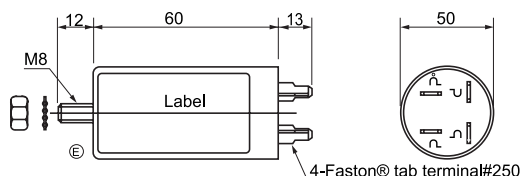

General Information

Series:	RG
Style:	Metal Cylinder
Description:	Noise Filters
RoHS:	Yes
Qualifications:	UL, TUV
Miscellaneous:	55 K Self-Temperature Rise Max.
Lead:	Fast On
Terminal Type:	Faston

Dimensions

D	50mm NOM
L	60mm NOM
LL	13mm NOM
L1	12mm NOM
Lead	Fast On

Packaging Specifications

Packaging:	Tray, Box
Packaging Quantity:	25
Weight:	220 g

Specifications

Voltage AC:	250 VAC
Voltage:	250 VDC, 1500 VAC Withstanding Voltage 1 Min. Line to Ground
Rated Current:	8 A (AC/DC)
Ripple Current:	8 A (AC/DC)
Temperature Range:	-25/+55°C
Leakage Current:	1 mA MAX (250 V 60 Hz)
Resistance:	100 MOhms MIN Insulation 500 VDC 1 Min. Line To Ground