


KEMET Part Number: RM4A(025)-220X185T0800
(UFSRM4025BT080)



KEMET, RM4A, Flex Suppressors, RFID

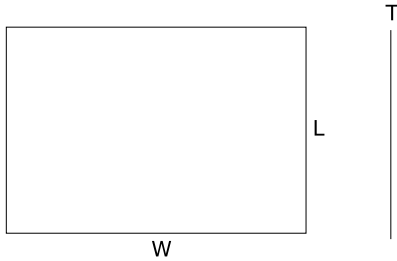

General Information	
Series:	RM4A
Style:	Sheet
Description:	Flex Suppressor Magnetic Sheet For RFID
Features:	High Magnetic Permeability Type, Low Magnetic Loss Type
RoHS:	Yes
Environment:	Halogen Free, PVC Free, Lead Free, RoHS Compliant

Dimensions	
Sheet Size	220x185mm
L	220mm NOM
W	185mm NOM
T	0.25mm NOM

Specifications	
Temperature Range:	-40/+85°C
Magnetic Permeability:	50 u At 13.56MHz
Effective Frequency:	13.56 Mhz
Resistance:	10 MOhms MIN
Specific Gravity:	3.6 Atm TYP

Packaging Specifications	
Tape Description:	Without PET Tape (Txx00)
Tape Thickness:	0.03mm
Weight:	38.29 g

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

