


KEMET Part Number: SBS9080-509T
(UDLSBS9080509T)

KEMET

a YAGEO company

KEMET, SBS9080, DC Line Filters, Common Mode

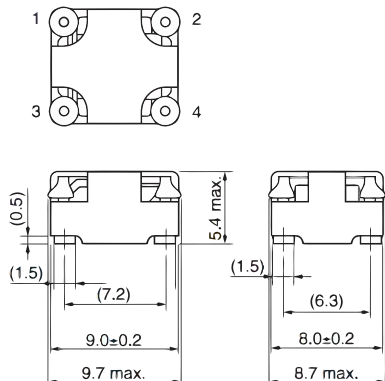

Dimensions	
L	9.7mm MAX
W	8.7mm MAX
T	5.4mm MAX
LL	1.5mm NOM
S	7.2mm MAX

Packaging Specifications	
Packaging:	T&R, 330mm
Packaging Quantity:	1000
Weight:	900 mg

General Information	
Series:	SBS9080
Style:	SMD
RoHS:	With Exemptions
REACH:	SVHC (Pb – CAS 7439-92-1)
SCIP Number:	4da5c62f-a115-440c-bba8-0dc143ab9e3e
Miscellaneous:	Withstanding Voltage: 125 VDC 1min Between Lines, Insulation Resistance: 10MOhm MIN (100 VDC Between Lines)

Specifications	
Voltage DC:	50 VDC
Temperature Range:	-25/+50°C
DC Resistance:	15 mOhms

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

KEMET

a YAGEO company