


KEMET Part Number: SCR47-140-S1R8A025JH-P
(UALBA1R8A025JH)



KEMET, SCR Three Phase, AC Line Filters, Common Mode, 2.5 mH

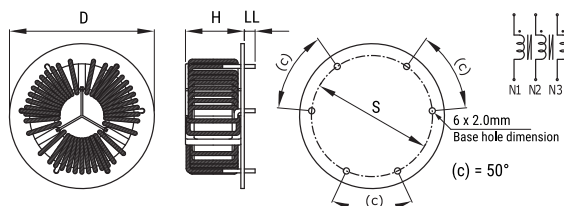

Dimensions

D	70mm MAX
H	36mm MAX
LL	5mm +/-1.5mm
S	56mm NOM
Wire Size	1.8mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	36
Component Weight:	170 g

General Information

Series:	SCR Three Phase
Style:	Through-Hole
Features:	High Impedance, Space Saving
RoHS:	Yes
Miscellaneous:	Temperature Rise Maximum: 55 K
Core:	Mn-Zn Ferrite

Specifications

Voltage AC:	250 VAC/VDC
Voltage DC:	250 VDC
Inductance:	2.5 mH (10 kHz)
Current:	14 A
Temperature Range:	-25/+120°C
DC Resistance:	9 mOhms

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

