


KEMET Part Number: SS30V-150200
(UAL30V15020000)

KEMET
a YAGEO company

KEMET, SS30V, AC Line Filters, Common Mode, 20 mH

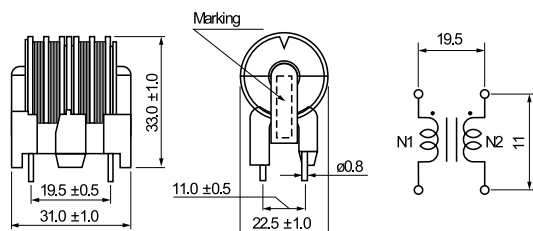

Dimensions

L	31mm +/-1mm
T	22.5mm +/-1mm
H	33mm +/-1mm
S	19.5mm +/-0.5mm
S1	11mm +/-0.5mm
Wire Size	0.55mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	200
Component Weight:	35.3 g

General Information

Series:	SS30V
Style:	Through-Hole
RoHS:	Yes
Notes:	Replacement For SS35V Type And SS28V Type.
Miscellaneous:	Temperature Rise Maximum: 45 K
Core:	Mn-Zn Ferrite

Specifications

Voltage AC:	250 VAC
Inductance:	20 mH
Current:	1.5 A
Temperature Range:	-25/+120°C
DC Resistance:	500 mOhms

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

KEMET
a YAGEO company