


**KEMET Part Number: SSHB10H-R11128**  
(UALSB1R1112800)

KEMET, SSHB10H, AC Line Filters, Dual Mode, 12.8 mH

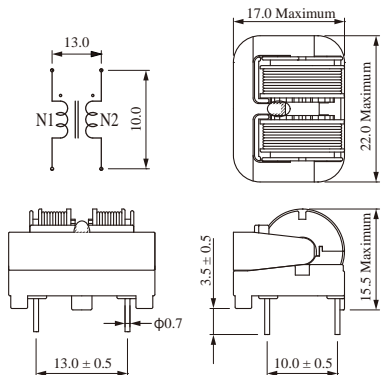

#### Dimensions

<b>L</b>	22mm MAX
<b>T</b>	17mm MAX
<b>H</b>	15.5mm MAX
<b>LL</b>	3.5mm +/-0.5mm
<b>S</b>	13mm +/-0.5mm
<b>S1</b>	10mm NOM

#### Packaging Specifications

<b>Packaging:</b>	Tray
<b>Packaging Quantity:</b>	300
<b>Weight:</b>	10 g

#### General Information

<b>Series:</b>	SSHB10H
<b>Style:</b>	Through-Hole
<b>RoHS:</b>	Yes
<b>Notes:</b>	Marking: R11 Lot No.
<b>Miscellaneous:</b>	Temperature Rise Maximum: 55 K

#### Specifications

<b>Voltage AC:</b>	250 VAC
<b>Inductance:</b>	12.8 mH (10 kHz)
<b>Current:</b>	1.1 A
<b>Temperature Range:</b>	-25/+120°C
<b>DC Resistance:</b>	390 mOhms