


KEMET Part Number: SU10VFC-R13025
(UALSU10VR13025)

KEMET, SU-10VFC-R, AC Line Filters, Common Mode, 2.5 mH

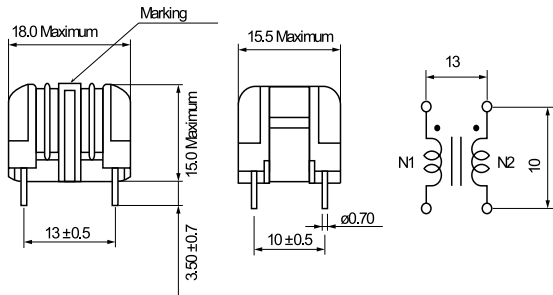

Dimensions

Dimension	Value
L	18mm MAX
T	15.5mm MAX
H	15mm MAX
LL	3.5mm +/-0.7mm
S	13mm +/-0.5mm
S1	10mm +/-0.5mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	700
Weight:	6.6 g

General Information

Series:	SU-10VFC-R
Style:	Through-Hole
RoHS:	Yes
Miscellaneous:	Temperature Rise Maximum: 50 K

Specifications

Voltage AC:	250 VAC
Inductance:	2500 uH
Current:	1.3 A
Temperature Range:	-25/+120°C
DC Resistance:	300 mOhms