 



KEMET Part Number: SU9HF-07015
(UALSU9HF070150)



KEMET, SU-9HF, AC Line Filters, Common Mode, 1.5 mH

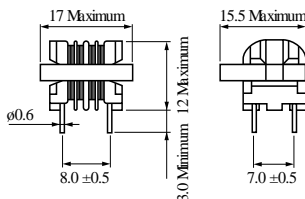

Dimensions	
L	17mm MAX
T	15.5mm MAX
H	12mm MAX
LL	3mm MIN
S	8mm +/-0.5mm
S1	7mm +/-0.5mm
Wire Size	0.23mm

Packaging Specifications	
Packaging:	Tray
Packaging Quantity:	1000
Component Weight:	3.3 g

General Information	
Series:	SU-9HF
Style:	Through-Hole
RoHS:	Yes
Miscellaneous:	Temperature Rise Maximum: 40 K
Core:	Mn-Zn Ferrite

Specifications	
Voltage AC:	250 VAC
Inductance:	1500 uH
Current:	700 mA
Temperature Range:	-25/+120°C
DC Resistance:	440 mOhms

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

