


KEMET, Z-PWZ, Ferrite Beads, Noise Suppression, 28 mOhms

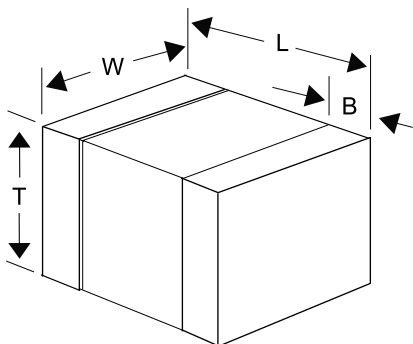

Dimensions	
Chip Size	0603
L	1.6mm +/-0.1mm
W	0.8mm +/-0.1mm
T	0.8mm +/-0.1mm
B	0.3mm +/-0.15mm

Packaging Specifications	
Packaging:	T&R
Packaging Quantity:	4000

General Information	
Series:	Z-PWZ
Style:	SMD Chip
Description:	Chip Bead, Power Line
Features:	For GHz Range Applications
RoHS:	Yes

Specifications	
Impedance:	30 Ohms (100 mHz)
Impedance Tolerance:	25%
Ripple Current:	2500 mA (MAX)
Temperature Range:	-40/+125°C
Resistance:	0.028 Ohms